

# Hydraulic Flexible/Non-Flexible Busbar Puncher



## CERTIFICATIONS



## FEATURES

Works with copper or aluminium busbar and nVent ERIFLEX Flexibar

Punches flat and clean hole edges

Punch pip to adjust the hole position

Quick setup with interchangeable punch and die system

Large range of round and oval punches and dies available

Can be tilted at a 45° angle for easier punching of formed busbar

Calibrated side and depth gauge and stop

Strong mechanical assembly

RoHS compliant

## SPECIFICATIONS


Table 1/2

| Catalog Number | Article Number | Operating Pressure | Busbar Thickness | Depth (D) | Height (H) | Width (W) |
|----------------|----------------|--------------------|------------------|-----------|------------|-----------|
| HYDR-BB-PUN    | 545680         | 700bar             | 12.7 mm Max      | 305mm     | 470 mm     | 120 mm    |

Table 2/2

| Catalog Number | Article Number | A      | Unit Weight |
|----------------|----------------|--------|-------------|
| HYDR-BB-PUN    | 545680         | 130 mm | 54 kg       |

## DIAGRAMS

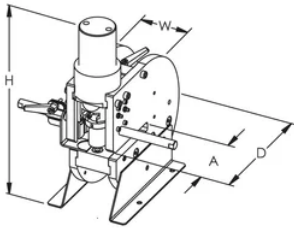

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical  
 Support

### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**