


Fusion G7 Half-Height Back Panel

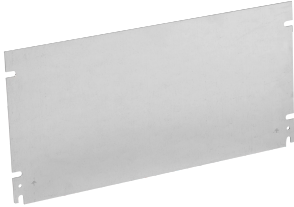

Galvanized steel half-height back panels. See table for thickness. M8 panel mounting nuts provided with 50-mm front-to-back sidemount accessory rails and side-mount accessory rail brackets.

FEATURES

one pc per package, include hardware

SPECIFICATIONS

Finish: Galvanized

Material: Mild Steel

Table 1/1

Catalog Number	Height	Width	Thickness	Fits Frame	Quick Ship
FUMP1060G010S	955mm	556mm	1.5mm	1000 x 600 or 600 x 1000mm	No
FUMP1590G010S	1455mm	855mm	1.5mm	1500 x 900mm	No
FUMP3030G010S	254mm	254mm	1.5mm	300 x 300mm	No
FUMP3040G010S	254mm	355mm	1.5mm	400 x 300 or 300 x 400mm	No
FUMP4030G010S	356mm	254mm	1.5mm	400 x 300 or 300 x 400mm	No
FUMP4040G010S	356mm	355mm	1.5mm	400 x 400mm	No
FUMP4060G010S	356mm	556mm	1.5mm	400 x 600mm	No
FUMP5040G010S	455mm	355mm	1.5mm	500 x 400mm	No
FUMP5050G010S	455mm	454mm	1.5mm	500 x 500mm	No
FUMP6040G010S	556mm	355mm	1.5mm	600 x 400 or 400 x 600mm	No
FUMP6050G010S	556mm	454mm	1.5mm	600 x 500mm	No
FUMP6060G010S	556mm	556mm	1.5mm	600 x 600mm	No
FUMP6080G010S	556mm	754mm	1.5mm	600 x 800mm	No
FUMP7050G010S	655mm	454mm	1.5mm	700 x 500mm	No
FUMP8060G010S	754mm	556mm	1.5mm	800 x 600 or 600 x 800mm	No
FUMP8080G010S	754mm	754mm	1.5mm	800 x 800mm	No
FUMP1080G010S	955mm	754mm	2mm	1000 x 800 or 800 x 1000mm	No

Catalog Number	Height	Width	Thickness	Fits Frame	Quick Ship
FUMP1260G010S	1156mm	556mm	2mm	1200 x 600mm	No
FUMP1280G010S	1156mm	754mm	2mm	1200 x 800mm	No
FUMP1290G010S	1156mm	855mm	2mm	1200 x 900mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE