


Inner Door, UID

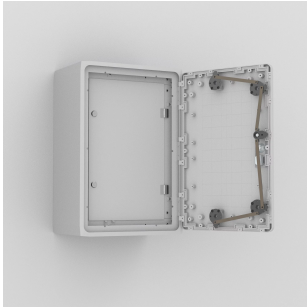

Displays and indicators can be mounted on a surface within the enclosure while covering other components, and preventing unauthorized access.

FEATURES

Description: For controls, meters, lamps, etc. Hinges can be mounted to allow left or right hand opening. Lock double-bit 3 mm insert. Distance between UID and enclosure door: 48 mm.

Material: Glass fibre reinforced polyester.

Finish: RAL 7035.

Protection: IP 20.

Delivery: 1 piece with mounting accessories.

A plain door to be mounted inside a wall mounted enclosure

Additional mounting surface providing two levels of access

Non authorized personnel have access to the controls on the inner door only

This accessory is often used in enclosures with glazed door

SPECIFICATIONS

Material: Glass Fiber Reinforced Polymer
Color: Light Gray
Color Code: RAL 7035
Finish: Smooth Matte

Table 1/1			
Catalog Number	Height	Width	Quick Ship
UID5050	500mm	500mm	No
UID5075	500mm	750mm	No
UID10050	1000mm	500mm	No
UID7550	750mm	500mm	No
UID7575	750mm	750mm	No
UID10075	1000mm	750mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE