


TFP Exhaust Grilles

Type 1 or Type 12 exhaust option for TFP Filter Fans

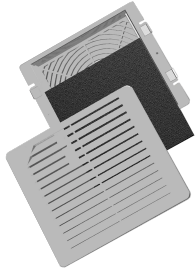

FEATURES

TFP Exhaust Grilles includes standard replacement filters that are washable foam (Type 1) or disposable (Type 12)

To maintain UL Type 12 rating on the enclosure, UL Type 12 filters must be used on the fan package inlet

SPECIFICATIONS

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Material	Finish
TEP4	12774	159mm	186mm	35mm	Composite	Smooth Matte
TEP4UL12	12777	159mm	186mm	35mm	Composite	Smooth Matte
TEP6	12775	197mm	224mm	32mm	Composite	Smooth Matte
TEP6UL12	12778	197mm	224mm	32mm	Composite	Smooth Matte
TEP6SS	11231	197mm	224mm	32mm	Stainless Steel 304	Brushed
TEP10	12776	299mm	329mm	34mm	Composite	Smooth Matte
TEP10UL12	12781	299mm	329mm	34mm	Composite	Smooth Matte
TEP10SS	11232	299mm	329mm	34mm	Stainless Steel 304	Brushed

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE