


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

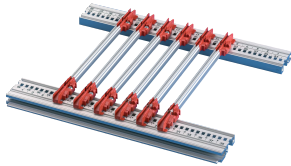

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

CERTIFICATIONS



FEATURES

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

SPECIFICATIONS

Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type:	Guide Rail
Type:	Middle Section

Table 1/2

Catalog Number	Material	Color	Package Quantity	Board Depth	Groove Width	Color Code
34560-891	Aluminum	Silver	1	160mm	2	

CatalogNumber	Material	Color	Package Quantity	Board Depth	Groove Width	Color Code
34560-892	Aluminum	Silver	1	220mm	2	
34560-893	Aluminum	Silver	1	280mm	2	
34560-900	Aluminum	Silver	1	1000mm	2	
34564-891	PVC	Grey	1	160mm	2	RAL 7035
34564-892	PVC	Grey	1	220mm	2	RAL 7035
34564-893	PVC	Grey	1	280mm	2	RAL 7035
34564-900	PVC	Grey	1	1000mm	2	RAL 7035

Table 2/2			
Catalog Number	Finish	Works With	Quick Ship
34560-891	Anodized	Subracks, Cases, Chassis	No
34560-892	Anodized	Subracks, Cases, Chassis	No
34560-893	Anodized	Subracks, Cases, Chassis	No
34560-900	Anodized	Subracks, Cases, Chassis	No
34564-891		Subracks, Cases, Chassis	No
34564-892		Subracks, Cases, Chassis	No
34564-893		Subracks, Cases, Chassis	No
34564-900		Subracks, Cases, Chassis	No

ADDITIONAL PRODUCT DETAILS

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE