


# VPX Backplane

The nVent SCHROFF VPX Backplane have excellent Signal Integrity for highest data transfer rates.

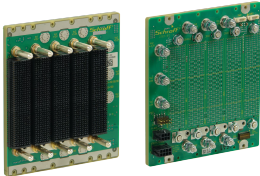

## CERTIFICATIONS



## FEATURES

In accordance with: VITA 46.0 VPX base standard; VITA 46.3 Serial RapidIO on VPX; VITA 46.4 PCI Express on VPX Fabric Connector; VITA 46.7 Ethernet on VPX Fabric Connector; VITA 46.11 System Management for VPX

DIP switch for system slot settings

JTAG connections

Lockable aux utility and sense connectors

M4 power studs for power supply, max. 22 A per slot for each voltage

## SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23001-812	Backplane	5	3U	VPX Full-mesh	4HP	MultiGig
23001-813	Backplane	5	3U	VPX Full-mesh	4HP	MultiGig
23001-814	Backplane	7	3U	VPX, VITA 65	5HP	MultiGig

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	Slot Width	ConnectorType
23001-815	Backplane	7	3U	VPX, VITA 65	5HP	MultiGig
23001-816	Backplane	10	6U	VPX, VITA 65	5HP	MultiGig
23001-834	Backplane	9	3U	VPX, VITA 65	5HP	MultiGig

Table 2/2

Catalog Number	Power Connector Type	Utility Connector Type	Width	Package Quantity	Certifications	Quick Ship
23001-812	Powerstuds M4	Microfit, 8-pin	120.67mm	1	VITA, RoHS	No
23001-813	Powerstuds M4	Microfit, 8-pin	120.67mm	1	RoHS, VITA	No
23001-814	Powerstuds M4	Microfit, 8-pin	186.46mm	1	VITA, RoHS	No
23001-815	Powerstuds M4	Microfit, 8-pin	186.46mm	1	RoHS, VITA	No
23001-816	Powerstuds M4	Microfit, 8-pin	262.55mm	1	VITA, RoHS	No
23001-834	Powerstuds M4	Microfit, 8-pin	253mm	1	VITA	No

## ADDITIONAL PRODUCT DETAILS

Other VPX Backplanes and custom VPX Backplane designs on request.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**