

2000 Beam Clamp Kit



FEATURES

Light duty system

Includes clamp and U channel

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	Length (L)	A	B	C	D
2300EG	570160	300mm	25 mm	25 mm	65 mm	25 mm
2200EG	570140	200mm	25 mm	25 mm	65 mm	25 mm
2400EG	570180	400mm	25 mm	25 mm	65 mm	25 mm

Table 2/2

Catalog Number	Article Number	E	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
2300EG	570160	30.5 mm	1700N	490N	340N
2200EG	570140	30.5 mm	1700N	490N	340N


Catalog Number	Article Number	E	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
2400EG	570180	30.5 mm	1700N	490N	340N

Thickness (T): 2 mm
Screw Diameter (Sc): 6
Hole Size (HS): 11 mm
Height (H): 12 mm
Width (W): 25 mm
Torque (TQ): 30 N·m
Flange Thickness (FT): 11 mm Max

ADDITIONAL PRODUCT DETAILS

For a secure grip the channel must extend to the outer edge of each beam clamp.

DIAGRAMS

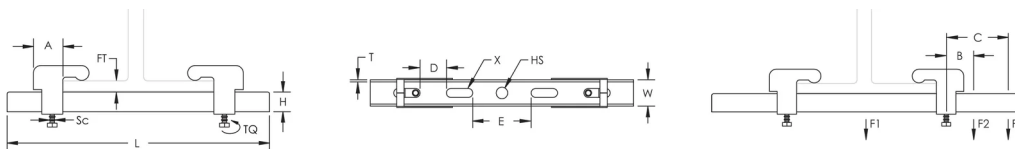

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

