

5000 Beam Clamp Kit



FEATURES

C-Channel system

Includes beam clamp and channel

SPECIFICATIONS

Finish: Hot-Dip Galvanized


Material: Steel

Table 1/1

Catalog Number	Article Number	Length (L)	Channel Type	Rod Size (RS)	Flange Thickness (FT)	Torque (TQ)
5500HD	335020	500mm	E5	10	3 - 30 mm	30 N·m
5800HD	335040	800mm	E5	10	3 - 30 mm	30 N·m
5400HD	335010	400mm	E5	10	3 - 30 mm	30 N·m
5300HD	335000	300mm	E5	10	3 - 30 mm	30 N·m
5600HD	335030	600mm	E5	10	3 - 30 mm	30 N·m

A	Static Load 1 F1	Static Load 2 F2
100 mm	3500 N	850 N
200 mm	1750 N	400 N
300 mm	1100 N	250 N
400 mm	800 N	200 N
500 mm	700 N	175 N
600 mm	500 N	125 N

DIAGRAMS

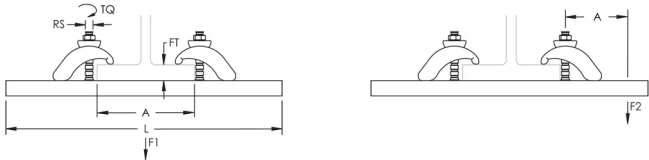

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

