


# P14 Position Coupler, Stainless Steel

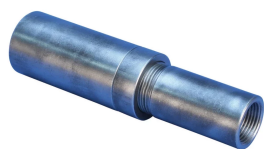

Stainless steel couplers are specified whenever corrosive environmental conditions combine with the need for high load-bearing strength. nVent LENTON stainless steel couplers are commonly used when the construction materials may come into contact with de-icing salts, salt water or marine environments. Typical applications include bridges and bridge decks.

## FEATURES

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

Duplex 2205 stainless steel provides a unique combination of strength and corrosion resistance

## SPECIFICATIONS

|                            |                                         |
|----------------------------|-----------------------------------------|
| <b>Finish:</b>             | Plain                                   |
| <b>Material:</b>           | Stainless Steel Duplex 2205 (EN 1.4462) |
| <b>Coupler Adjustment:</b> | Standard                                |

Table 1/2

| Catalog Number | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) |
|----------------|--------------------|----------------|--------------------|--------------|---------------|---------------|
| EL12P14LSSN    | 12 mm              | #4             | 10M                | 25 mm        | 98 mm         | 105 mm        |
| EL20P14LSSN    | 20 mm              | #6             | 20M                | 35 mm        | 152 mm        | 163 mm        |
| EL16P14LSSN    | 16 mm              | #5             | 15M                | 30 mm        | 112 mm        | 119 mm        |
| EL25P14LSSN    | 25 mm              | #8             | 25M                | 45 mm        | 169 mm        | 180 mm        |
| EL32P14LSSN    | 32 mm              | #10            |                    | 60 mm        | 192 mm        | 203 mm        |

Table 2/2


| Catalog Number | Bar Depth (BD) | Bar Gap 1 (BG1) | Bar Gap 2 (BG2) | Coupler Body (CB) | Unit Weight |
|----------------|----------------|-----------------|-----------------|-------------------|-------------|
| EL12P14LSSN    | 19mm           | 60mm            | 67mm            | 46mm              | 0.26 kg     |
| EL20P14LSSN    | 35mm           | 82mm            | 93mm            | 76mm              | 0.36 kg     |
| EL16P14LSSN    | 24mm           | 64mm            | 71mm            | 54mm              | 0.44 kg     |
| EL25P14LSSN    | 40mm           | 89mm            | 100mm           | 86mm              | 1.32 kg     |
| EL32P14LSSN    | 45mm           | 102mm           | 113mm           | 96mm              | 2.72 kg     |

**Designed to Meet:** AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

## ADDITIONAL PRODUCT DETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

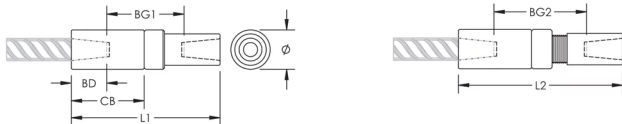

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**