

100T Heavy Duty Trapeze Loop Hanger



CERTIFICATIONS



FEATURES

Recommended for the suspension of stationary non-insulated pipe lines

Designed for heavy duty trapeze installations where space is limited and attachment to structure is difficult

UL® Listed to support trapeze assembly loads of 8" pipe size

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

Meets NFPA®-13 requirements for trapeze loop hangers

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
100T0200EG	2" Min	2 1/2"	1/2"	5"	2 3/8"
100T0250EG	2 1/2"	3"	1/2"	5 5/8"	2 13/16"

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
100T0300EG	3"	3 5/8"	1/2"	6 9/16"	3 1/2"
100T0350EG	3 1/2"	4 1/8"	1/2"	7"	3 5/8"
100T0400EG	4"	4 5/8"	1/2"	7 3/4"	4"


Table 2/2

Catalog Number	C	Static Load (F)
100T0200EG	1 7/16"	1250lbf
100T0250EG	1 5/8"	1250lbf
100T0300EG	1 7/8"	1250lbf
100T0350EG	1 7/8"	1250lbf
100T0400EG	2"	1250lbf

ADDITIONAL PRODUCT DETAILS

Upper trapeze support and lower hanger must be able hold the maximum load intended for the trapeze assembly.

DIAGRAMS

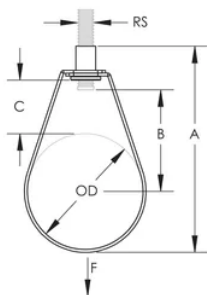

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

