

101 Loop Hanger for Copper Tube



FEATURES

Recommended for the suspension of stationary non-insulated copper tube lines

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

SPECIFICATIONS

Finish: Copper Electroplated;Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
1010050CP	1/2"	5/8"	3/8"	3 3/16"	1 5/8"	1 9/16"
1010075CP	3/4"	7/8"	3/8"	3 1/8"	1 3/8"	1 3/16"
1010100CP	1"	1 1/8"	3/8"	3 1/8"	1 5/16"	1"
1010125CP	1 1/4" Min	1 3/8"	3/8"	3 3/16"	1 1/4"	13/16"
1010150CP	1 1/2"	1 5/8"	3/8"	3 5/8"	1 9/16"	15/16"
1010200CP	2" Min	2 1/8"	3/8"	3 13/16"	1 7/16"	5/8"

CatalogNumber	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
1010250CP	2 1/2"	2 5/8"	3/8"	4 7/16"	1 11/16"	9/16"
1010300CP	3"	3 1/8"	1/2"	5 11/16"	2 1/2"	1 5/16"
1010400CP	4"	4 1/8"	1/2"	7 1/8"	3 7/16"	1 3/4"

Table 2/2

Catalog Number	Static Load (F)
1010050CP	180lbf
1010075CP	180lbf
1010100CP	180lbf
1010125CP	180lbf
1010150CP	180lbf
1010200CP	180lbf
1010250CP	200lbf
1010300CP	250lbf
1010400CP	360lbf

DIAGRAMS

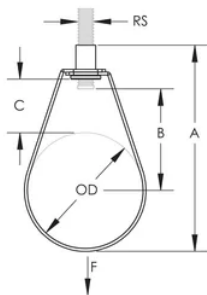

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

