

104 Loop Hanger for Plastic Pipe



FEATURES

Recommended for the suspension of stationary flexible EPDM or Polypropylene plastic piping

Use hanger with V-trough for continuous support of flexible or hot piping services

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Pipe Size	Rod Size (RS)	A	Static Load (F)
1040100EG	1/2" - 2"	3/8"	5 7/8"	17lbf
1040200EG	2 1/2" - 4"	1/2"	9 1/4"	17lbf

Part Number	Pipe Size	OD	B	C
1040100EG	1/2"	0.840"	4 1/8"	4"
	3/4"	1.050"	3 15/16"	3 3/4"
	1"	1.315"	3 3/4"	3 7/16"
	1 1/4"	1.660"	3 1/2"	3"
	1 1/2"	1.900"	3 3/8"	2 11/16"
	2"	2.375"	3"	2 1/8"
1040200EG	2 1/2"	2.875"	5 3/4"	4 11/16"
	3"	3.500"	5 5/16"	3 15/16"
	3 1/2"	4.000"	4 15/16"	3 3/8"
	4"	4.500"	4 5/8"	2 3/4"

DIAGRAMS

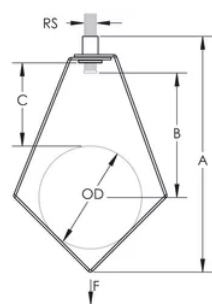

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

