

108 Two Hole Strap for CPVC Pipe



CERTIFICATIONS



FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screws

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2


Catalog Number	Pipe Size	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1080075EG	3/4"	1.05"	7/32"	3 1/4"	2 1/4"	1 3/16"
1080100EG	1"	1.31"	7/32"	3 1/2"	2 1/2"	1 3/16"
1080125EG	1 1/4" Min	1.66"	7/32"	4 1/4"	3 1/4"	1 3/16"

CatalogNumber	Pipe Size	Outer Diameter (OD)	Hole Size (HS)	A	B	C
1080150EG	1 1/2"	1.9"	7/32"	4 7/16"	3 7/16"	1 3/16"
1080200EG	2" Min	2 3/8"	7/32"	4 15/16"	3 15/16"	1 3/16"

Table 2/2

Catalog Number	Hanger Spacing
1080075EG	5.5' Max
1080100EG	6' Max
1080125EG	6.5' Max
1080150EG	7' Max
1080200EG	8' Max

DIAGRAMS

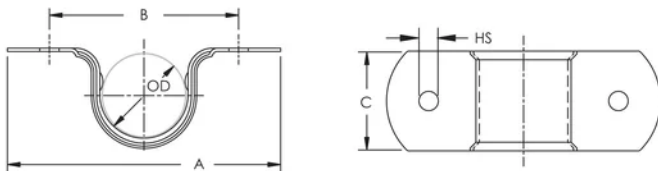

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

