

115 Standard Duty Loop Hanger



The 115 Standard Duty Loop Hanger is ideal for suspending stationary, non-insulated pipe lines, including CPVC pipes, in fire sprinkler systems. A knurled insert nut helps simplify vertical adjustments and flared edges on the base (1/2" to 4" sizes) help protect pipes from coming into contact with any sharp edges of the hanger.

CERTIFICATIONS



FEATURES

Flared edges help prevent any sharp surfaces from coming into contact with the pipe (1/2" to 4" sizes)

Retained insert nut helps ensure the loop hanger and insert nut stay together

Recommended for the suspension of stationary non-insulated pipe lines

Manufactured to use the minimum rod size permitted by NFPA® for fire sprinkler piping

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
1150050EG	1/2"	0.84"	3/8"	2 13/16"	1 1/8"
1150075EG	3/4"	1.05"	3/8"	3"	1 3/16"


Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
1150100EG	1"	1.31"	3/8"	3 1/4"	1 3/8"
1150125EG	1 1/4" Min	1.66"	3/8"	3 9/16"	1 1/2"
1150150EG	1 1/2"	1.9"	3/8"	3 13/16"	1 5/8"
1150200EG	2" Min	2 3/8"	3/8"	4 1/4"	1 7/8"
1150250EG	2 1/2"	2 7/8"	3/8"	5 15/16"	3 7/16"
1150300EG	3"	3 1/2"	3/8"	6 9/16"	3 1/2"
1150350EG	3 1/2"	4"	3/8"	7 1/16"	3 3/4"
1150400EG	4"	4 1/2"	3/8"	7 9/16"	4"
1150500EG	5"	5 9/16"	1/2"	9 13/16"	4 3/4"
1150600EG	6"	6 5/8"	1/2"	11 5/16"	6 5/16"
1150800EG	8"	8 5/8"	1/2"	12 7/8"	6 7/8"

Table 2/2

Catalog Number	C	Static Load (F)	Certifications
1150050EG	1"	300lbf	cUL, UL
1150075EG	15/16"	300lbf	UL, cUL, FM Approved, Pipe Hanger Components
1150100EG	15/16"	300lbf	FM Approved, Pipe Hanger Components, UL, cUL
1150125EG	15/16"	300lbf	FM Approved, Pipe Hanger Components, UL, cUL
1150150EG	15/16"	300lbf	cUL, FM Approved, Pipe Hanger Components, UL
1150200EG	15/16"	300lbf	cUL, FM Approved, Pipe Hanger Components, UL

Catalog Number	C	Static Load (F)	Certifications
1150250EG	2"	525lbf	cUL, FM Approved, Pipe Hanger Components, UL
1150300EG	1 15/16"	525lbf	UL, cUL, FM Approved, Pipe Hanger Components
1150350EG	1 15/16"	585lbf	FM Approved, Pipe Hanger Components, UL, cUL
1150400EG	1 15/16"	650lbf	cUL, FM Approved, Pipe Hanger Components, UL
1150500EG	2 1/4"	1000lbf	UL, cUL, FM Approved, Pipe Hanger Components
1150600EG	3 5/16"	1000lbf	cUL, FM Approved, Pipe Hanger Components, UL
1150800EG	2 7/8"	1000lbf	FM Approved, Pipe Hanger Components, UL, cUL

DIAGRAMS

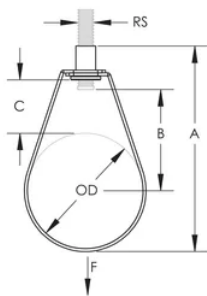

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

