

328 Threaded Steel Side Beam Attachment



CERTIFICATIONS



FEATURES

Fastens to wall or the side of a joist to support hanger rod

Pre-threaded

Conforms with Federal Specification WW-H-171 (Type 35), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 34)

SPECIFICATIONS

Finish: Plain

Material: Steel

Table 1/2

Catalog Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	A	B	C
3280037PL	3/8"	17/32"	13/32"	2 9/16"	1"	1 1/4"
3280050PL	1/2"	17/32"	13/32"	2 9/16"	1"	1 1/4"

Table 2/2

Catalog Number	Static Load 1 (F1)	Static Load 2 (F2)	Certifications
3280037PL	560lb	620lb	cUL, UL
3280050PL	560lb	620lb	


ADDITIONAL PRODUCT DETAILS

Refer to Static Load 1 when used with lag screw. Refer to Static Load 2 with bolt to steel.

Follow fastener manufacturer's recommended shear and pull-out strength when fastening to the structure. Fastener not included.

Install in accordance with applicable code.

DIAGRAMS

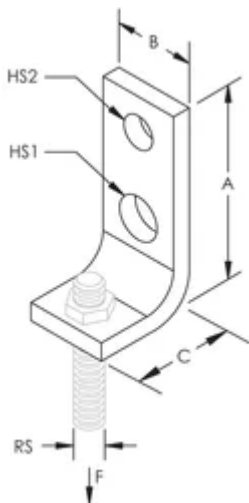

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

