

365M Malleable Iron Wall or Ceiling Plate



FEATURES

Structural attachment to support hanger rod from a ceiling or a wall

SPECIFICATIONS

Material: Cast Iron

Table 1/2

Catalog Number	Finish	Rod Size (RS)	Hole Size (HS)	A	B	Pipe Size
365M0037CP	Copper Electroplated	3/8"	1/4"	15/32"	1 15/16"	2" Max
365M0050CP	Copper Electroplated	1/2"	1/4"	15/32"	1 15/16"	3 1/2" Max
365M0037PL	Plain	3/8"	1/4"	15/32"	1 15/16"	2" Max
365M0037EG	Electrogalvanized	3/8"	1/4"	15/32"	1 15/16"	2" Max
365M0050EG	Electrogalvanized	1/2"	1/4"	15/32"	1 15/16"	3 1/2" Max
365M0050PL	Plain	1/2"	1/4"	15/32"	1 15/16"	3 1/2" Max

Table 2/2


Catalog Number	Static Load (F)
----------------	-----------------

365M0037CP	180lbf
365M0050CP	180lbf
365M0037PL	180lbf
365M0037EG	180lbf
365M0050EG	180lbf
365M0050PL	180lbf

ADDITIONAL PRODUCT DETAILS

Follow fastener manufacturer's recommended shear and pull-out strength when fastening to the structure. Fastener not included.

DIAGRAMS

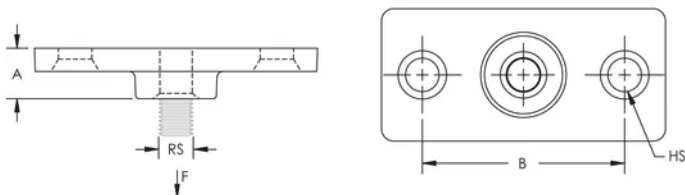

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

