

402 Clevis Hanger for Copper Tube, Light Duty



FEATURES

Recommended for the suspension of stationary non-insulated copper tube lines

Conforms with U.S. Federal Specification WW-H-171 (Type 12), Manufacturers Standardization Society (MSS) SP-58 (Type 1)

SPECIFICATIONS

Finish: Copper Electroplated

Material: Steel


Table 1/2

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
4020050CP	1/2"	5/8"	3/8"	2 1/16"	1"	1/4"
4020075CP	3/4"	0.74"	3/8"	2 5/16"	1 1/4"	1/4"
4020100CP	1"	1 1/8"	3/8"	3"	1 5/16"	9/16"
4020125CP	1 1/4" Min	1 3/8"	3/8"	2 3/4"	1 3/4"	9/16"
4020150CP	1 1/2"	1 5/8"	3/8"	3 5/16"	2 1/16"	3/4"
4020200CP	2" Min	2 1/8"	3/8"	4.06"	2 7/16"	1"

CatalogNumber	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
4020250CP	2 1/2"	2 5/8"	1/2"	4 13/16"	2 7/8"	11/16"
4020300CP	3"	3 1/8"	1/2"	5 1/2"	3 1/4"	1 1/8"
4020400CP	4"	4 1/8"	1/2"	6 3/4"	4.06"	1 9/16"

Table 2/2	
Catalog Number	Static Load (F)
4020050CP	215lbf
4020075CP	215lbf
4020100CP	215lbf
4020125CP	215lbf
4020150CP	215lbf
4020200CP	215lbf
4020250CP	250lbf
4020300CP	300lbf
4020400CP	440lbf

DIAGRAMS

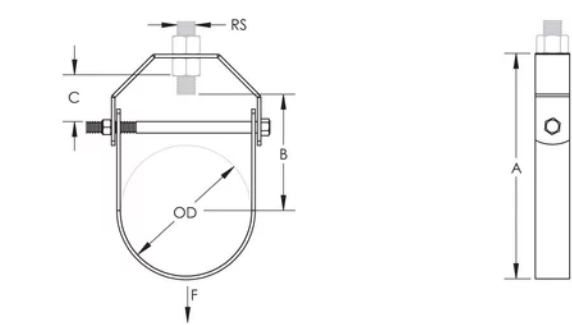

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

