

406 Clevis Hanger, Stainless Steel



CERTIFICATIONS



FEATURES

Recommended for the suspension of stationary non-insulated stainless steel pipe lines

Conforms with U.S. Federal Specification WW-H-171 (Type 1), Manufacturers Standardization Society (MSS) SP-58 (Type 1)

SPECIFICATIONS

Material: Stainless Steel 304 (EN 1.4301)

Table 1/2

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
4060050S4	1/2"	0.84"	3/8"	2 1/8"	11/16"	1/4"
4060075S4	3/4"	1.05"	3/8"	2 3/8"	1 3/16"	3/8"
4060100S4	1"	1.31"	3/8"	2 3/4"	1 1/2"	9/16"


CatalogNumber	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
4060125S4	1 1/4" Min	1.66"	3/8"	3 5/16"	1 13/16"	11/16"
4060150S4	1 1/2"	1.9"	3/8"	3 15/16"	2 3/8"	11/16"
4060200S4	2" Min	2 3/8"	3/8"	4 1/2"	2 5/8"	1 1/8"
4060250S4	2 1/2"	2 7/8"	1/2"	5 1/4"	3"	11/16"
4060300S4	3"	3 1/2"	1/2"	6"	3 7/16"	7/8"
4060350S4	3 1/2"	4"	1/2"	6 1/2"	3 11/16"	1 3/8"
4060400S4	4"	4 1/2"	5/8"	7 3/4"	4 5/8"	1 3/4"
4060500S4	5"	5 9/16"	5/8"	9 3/4"	5 5/8"	2 3/16"
4060600S4	6"	6 5/8"	3/4"	11 3/4"	7 1/16"	2 11/16"
4060800S4	8"	8 5/8"	3/4"	14"	8"	3 1/8"
4061000S4	10"	10 3/4"	7/8"	16 1/2"	9 1/16"	2 9/16"
4061200S4	12"	12 3/4"	7/8"	18 5/8"	10 3/16"	3 1/16"

Table 2/2

Catalog Number	Static Load (F)	Certifications
4060050S4	600lbf	
4060075S4	600lbf	
4060100S4	600lbf	
4060125S4	600lbf	
4060150S4	600lbf	

Catalog Number	Static Load (F)	Certifications
4060200S4	610lbf	
4060250S4	1130lbf	FM Approved, Pipe Hanger Components
4060300S4	1130lbf	FM Approved, Pipe Hanger Components
4060350S4	1130lbf	FM Approved, Pipe Hanger Components
4060400S4	1130lbf	FM Approved, Pipe Hanger Components
4060500S4	1430lbf	FM Approved, Pipe Hanger Components
4060600S4	1940lbf	FM Approved, Pipe Hanger Components
4060800S4	2000lbf	FM Approved, Pipe Hanger Components
4061000S4	3600lbf	
4061200S4	3800lbf	

DIAGRAMS

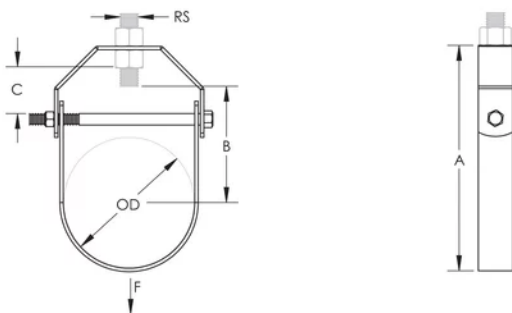

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

