

455 Malleable Split Ring Hanger



FEATURES

Recommended for the suspension of stationary non-insulated pipe lines

Allows for piping runs close to ceiling or walls

Conforms with Federal Specification WW-H-171 (Type 25), Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICATIONS

Material: Cast Iron

Table 1/2

Catalog Number	Finish	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
4550050EG	Electrogalvanized	1/2"	0.84"	3/8"	1 1/2"	3/8"
4550050PL	Plain	1/2"	0.84"	3/8"	1 1/2"	3/8"
4550075EG	Electrogalvanized	3/4"	1.05"	3/8"	1 3/4"	7/16"
4550075PL	Plain	3/4"	1.05"	3/8"	1 3/4"	7/16"
4550100EG	Electrogalvanized	1"	1.31"	3/8"	2"	7/16"
4550100PL	Plain	1"	1.31"	3/8"	2"	7/16"

CatalogNumber	Finish	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B
4550125EG	Electrogalvanized	1 1/4" Min	1.66"	3/8"	2 3/8"	1/2"
4550125PL	Plain	1 1/4" Min	1.66"	3/8"	2 3/8"	1/2"
4550150EG	Electrogalvanized	1 1/2"	1.9"	3/8"	2 5/8"	1/2"
4550150PL	Plain	1 1/2"	1.9"	3/8"	2 5/8"	1/2"
4550200EG	Electrogalvanized	2" Min	2 3/8"	3/8"	3 1/8"	1/2"
4550200PL	Plain	2" Min	2 3/8"	3/8"	3 1/8"	1/2"
4550250EG	Electrogalvanized	2 1/2"	2 7/8"	1/2"	3 1/4"	5/8"
4550250PL	Plain	2 1/2"	2 7/8"	1/2"	3 1/4"	5/8"
4550300EG	Electrogalvanized	3"	3 1/2"	1/2"	4 3/8"	5/8"
4550300PL	Plain	3"	3 1/2"	1/2"	4 3/8"	5/8"
4550400EG	Electrogalvanized	4"	4 1/2"	1/2"	5 3/8"	11/16"
4550400PL	Plain	4"	4 1/2"	1/2"	5 3/8"	11/16"

Table 2/2


Catalog Number	Static Load (F)
4550050EG	180lbf
4550050PL	180lbf
4550075EG	180lbf
4550075PL	180lbf
4550100EG	180lbf

Catalog Number	Static Load (F)
4550100PL	180lbf
4550125EG	180lbf
4550125PL	180lbf
4550150EG	180lbf
4550150PL	180lbf
4550200EG	180lbf
4550200PL	180lbf
4550250EG	300lbf
4550250PL	300lbf
4550300EG	300lbf
4550300PL	300lbf
4550400EG	300lbf
4550400PL	300lbf

ADDITIONAL PRODUCT DETAILS

Bolt and rivet are carbon steel.

DIAGRAMS

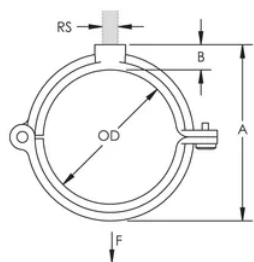

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

