

512 nVent CADDY EZ Riser for Close Quarters



The 512 nVent CADDY EZ Riser for Close Quarters is a quick-closing pipe clamp, ideal for vertical pipe in tight spaces. This innovative solution is designed for situations where a full-sized clamp would not fit—typically, when a pipe is close to the corner of a room. Ready-to-use out of the box, this solution has slotted holes to simplify assembly and eliminate loose hardware. Due to the serrated washer-head design, installers can easily assemble the EZ Riser for Close Quarters with just a single tool.

CERTIFICATIONS



FEATURES

Only one tool needed to tighten due to serrated wash-heads

Short ears allow for use in confined spaces or corners

Conforms with Federal Specification WW-H-171 (Type 8), Manufacturers Standardization Society (MSS) SP-58 (Type 8)

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Pipe Size	Outer Diameter (OD)	Hole Size (HS)	A	B	Static Load (F)
5120100EG	1"	1.31"	7/16"	5"	1"	255lbf
5120125EG	1 1/4" Min	1.66"	7/16"	5 5/8"	1"	255lbf
5120150EG	1 1/2"	1.9"	7/16"	6 1/8"	1"	255lbf

CatalogNumber	Pipe Size	Outer Diameter (OD)	Hole Size (HS)	A	B	Static Load (F)
5120200EG	2" Min	2 3/8"	7/16"	6 5/8"	1 3/16"	255lbf
5120250EG	2 1/2"	2 7/8"	7/16"	7 5/8"	1 3/16"	390lbf
5120300EG	3"	3 1/2"	9/16"	8 5/8"	1 3/16"	530lbf
5120400EG	4"	4 1/2"	9/16"	10 1/4"	1 1/2"	810lbf
5120600EG	6"	6 5/8"	9/16"	14 5/16"	2"	1570lbf

DIAGRAMS

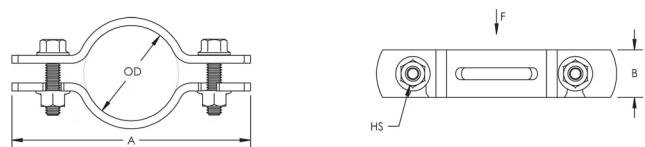

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

