


# Adjustable Mud Ring

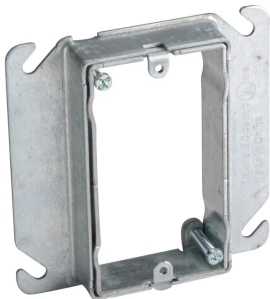

## CERTIFICATIONS



## FEATURES

Adjustable mud ring accommodates various thicknesses of drywall

Can be adjusted after the installation of drywall

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/1

| Catalog Number | Gang | Box Size | Drywall Thickness |
|----------------|------|----------|-------------------|
| AMR1020SG      | 1    | 4"       | 5/8" - 1 1/4"     |
| AMR1024DG41    | 2    | 4 11/16" | 5/8" - 1 1/4"     |
| AMR1224SG41    | 1    | 4 11/16" | 5/8" - 1 1/4"     |

| Catalog Number | Gang | Box Size | Drywall Thickness |
|----------------|------|----------|-------------------|
| AMR1024DG      | 2    | 4"       | 5/8" - 1 1/2"     |
| AMR1224SG      | 1    | 4"       | 3/4" - 1 1/2"     |
| AMR1224TG      | 3    |          | 3/4" - 1 1/2"     |

## ADDITIONAL PRODUCT DETAILS

Can be used with nVent CADDY Adjustable Mud Ring, Extension (sold separately) that is attached to inner ring for additional depths up to 2¼ in

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

