

ADK Strut End Cap



The nVent CADDY ADK Strut End Caps provide a safe and fast solution for handling sharp-edged strut channels. The ADK Caps are easily inserted into the ends of factory or field-cut strut channels and help prevent potential injuries caused by rough edges found on material ends. Additionally, this simple solution works with multiple strut channel profile types and is available in several different colors to suit individual applications.

FEATURES

Fits into ERISTRUT Type A, B, C and D strut channel, both slotted and solid

When separated, provides two end caps for ERISTRUT Type C channel

SPECIFICATIONS

Material: Polyethylene

Table 1/2


Catalog Number	Color	Strut Type	Height (H)	Width (W)	A	B
ADK421RD	Red	A (1 5/8" x 1 5/8"), C (13/16" x 1 5/8")	1 5/8"	1 5/8"	13/16"	5/16"
ADK421GY	Gray	A (1 5/8" x 1 5/8"), C (13/16" x 1 5/8")	1 5/8"	1 5/8"	13/16"	5/16"
ADK421	Blue	A (1 5/8" x 1 5/8"), C (13/16" x 1 5/8")	1 5/8"	1 5/8"	13/16"	5/16"

Table 2/2

Catalog Number	Thickness (T)
----------------	---------------

ADK421RD	7/16"
ADK421GY	7/16"
ADK421	7/16"

DIAGRAMS

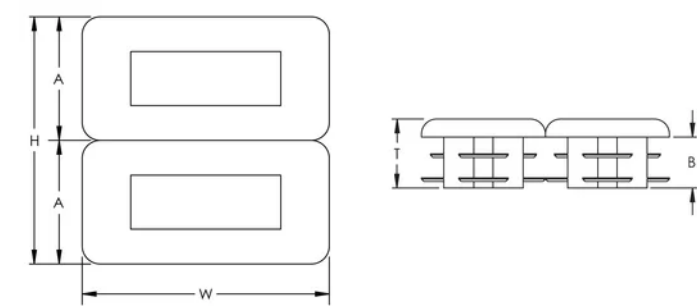

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

