

B18-C03 Box/Multiple Conduit Hanger



The nVent CADDY B18-C03 Box/Conduit Hanger presents an efficient and secure solution for the installation of electrical boxes and conduit in overhead applications by streamlining the process with a single-threaded rod drop. The system is designed to provide greater efficiency in the field with our class-leading range of nVent CADDY Conduit Clamps.

CERTIFICATIONS



FEATURES

Scoreline breakaway feature can be easily modified by hand while maintaining UL listing

Eliminates need for offset bending conduit

Comes with three conduit clips attached to each side

Labor and time savings due to built-in first means of support

Provides independent first means of support for conduit and/or MC/AC cable

NEC® and CEC compliant

SPECIFICATIONS

Table 1/2


Catalog Number	Material	Finish	Flexible Conduit Size	MC/AC Cable Size	Hole Size (HS)	Hole Type
6M3B18ACO	Spring Steel	nVent CADDY Armour	3/8"	14-2 to 12-3	1/4"	Plain

Table 2/2

Catalog Number	Length (L)	Width (W)
----------------	------------	-----------

6M3B18ACO	19"	5.1"
-----------	-----	------

DIAGRAMS

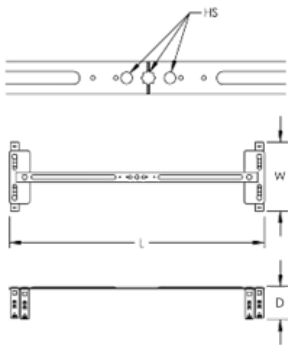

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

