


# BC-M Conduit to Beam Clamp



## CERTIFICATIONS

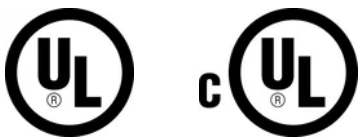

## FEATURES

Easy installation to beam flanges

Eliminates offset bending conduit

Conduit clip rotates 360 degrees

## SPECIFICATIONS

**Finish:** nVent CADDY Armour


**Material:** Spring Steel

Table 1/1

Catalog Number	EMT Conduit Size	Rigid Conduit/Pipe Size	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load (F)
BC812M	1/2", 3/4"	1/2", 3/4"	0.710" - 1.18"	1/2" Max	20 ft·lbf	100lb
BC16M	3/4", 1"	3/4", 1"	0.920" - 1.38"	1/2" Max	20 ft·lbf	100lb

CatalogNumber	EMT Conduit Size	Rigid Conduit/Pipe Size	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load (F)
BC20M	1 1/4"	1 1/4"		1/2" Max	20 ft·lbf	100lb
BC24M	1 1/2"	1 1/2"	1 1/2"	1/2" Max	20 ft·lbf	100lb
BC32M	2"	2"		1/2" Max	20 ft·lbf	100lb

## DIAGRAMS

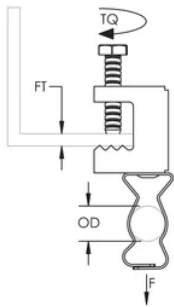

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

