


BC14 Welded Beam Clamp, Heavy Duty

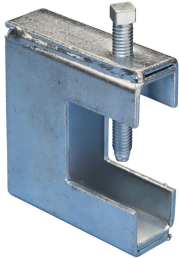

CERTIFICATIONS



BABA

FEATURES

Structural attachment to beams to support threaded rod

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Rod Size (RS)	Flange Thickness (FT)	B	Screw Diameter (Sc)
BC140037EG	Steel	Electrogalvanized	3/8"	1 5/8" Max	1 5/8"	3/8"


Table 2/2

Catalog Number	Screw Length (L)	Torque (TQ)	Static Load (F)
BC140037EG	2 3/4"	5 ft·lbf	800lb

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

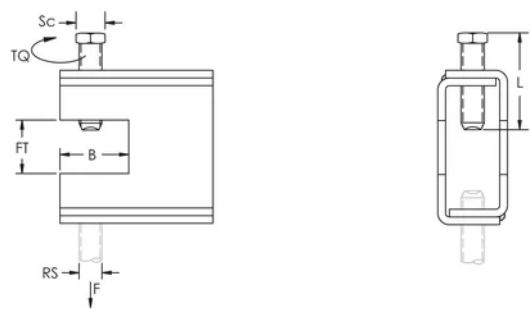

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

