

Cable/Conduit to Wire Clip



CERTIFICATIONS



BABA



FEATURES

Supports cable and conduit without bending drop wire

Faster installation than traditional methods

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	EMT Conduit Size	MC/AC Cable Size	Outer Diameter (OD)	Wire Size	Hole Size (HS)	Ultimate Static Load (F)
PCS2	1/2", 3/4"	10-3 to 6-3	0.600" - 0.9"	#12 - #8	1/4"	25lb
PCS1		14-2 to 10-3	0.450" - 0.6"	#12 - #8	1/4"	25lb

Table 2/2


Catalog Number	Certifications
----------------	----------------

PCS2	ITB
PCS1	cUL, UL, ITB

ADDITIONAL PRODUCT DETAILS

NEC® 300.11 requires dedicated drop wire/rod and EC311.

DIAGRAMS

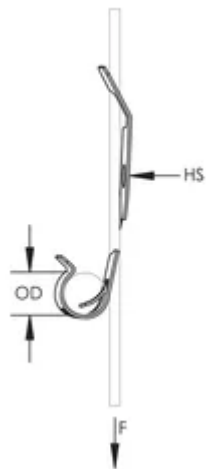

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

