

DOSR Double Offset Surge Restraint for CPVC Pipe



CERTIFICATIONS



FEATURES

Provides quick and easy snap-in installation of pipe

Built-in nail tab allows for fast, temporary mounting to any surface

Rated for use with CPVC fire sprinkler pipe

Positions pipe 1-1/2" (38 mm) out and up from the mounting surface eliminating the need for wooden spacer blocks

Meets the UL® 203 stringent upward thrust requirement

UL® Listed as both a hanger and restraint in the double offset orientation

Complies with static load requirements of NFPA® 13

Includes mounting screws

Can be used with 3TW backing nut on composite wood joist installations

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel


Table 1/2

Catalog Number	Pipe Size	Hole Size (HS)	Height (H)	Width (W)	Depth (D)	A
DOSR075	3/4"	0.2"	5.2"	1"	3 1/2"	1 1/2"
DOSR100	1"	0.2"	5.8"	1"	3.4"	1 1/2"

Table 2/2

Catalog Number	Thickness (T)	Hanger Spacing
DOSR075	18ga	6' Max
DOSR100	18ga	6' Max

DIAGRAMS

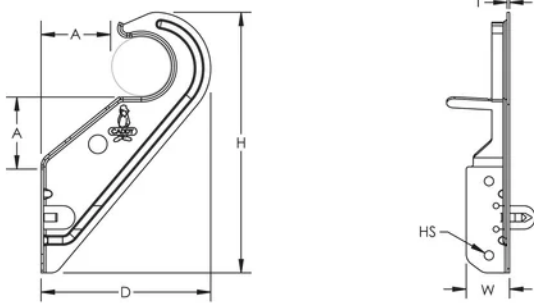

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

