

Drop-In Anchor



CERTIFICATIONS



FEATURES

Internal thread provides easy removal and serviceability

Installs flush or below the base surface

Suitable for redundant non-structural systems on cracked and non-cracked concrete

Fire resistance class R30-R120 for design of anchorages under exposure to fire


SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Hole Size (HS)	Length (L)	Drill Bit Diameter	Certifications
CAM6030	Steel	Electrogalvanized	6"	1.18"	0.31"	CE, 14-0135, CE, 14-0068
CAM8030S6	Stainless Steel 316 (EN 1.4401)		8"	1.18"	0.39"	VdS, CE, 14-0068
CAM8030	Steel	Electrogalvanized	8"	1.18"	0.39"	CE, 14-0068, VdS, CE, 14-0135

CatalogNumber	Material	Finish	Hole Size (HS)	Length (L)	Drill Bit Diameter	Certifications
CAM10040	Steel	Electrogalvanized	10"	1.57"	0.47"	FM Approved, Anchor, CE, 14-0135, CE, 14-0068, VdS
CAM10040S6	Stainless Steel 316 (EN 1.4401)		10"	1.57"	0.47"	CE, 14-0068, VdS
CAM12050	Steel	Electrogalvanized	12"	1.97"	0.59"	VdS, CE, 14-0135, CE, 14-0068, FM Approved, Anchor

DIAGRAMS

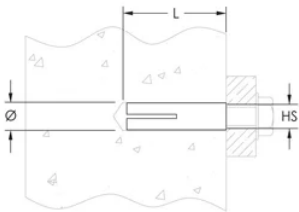

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

