

nVent CADDY Pyramid Rooftop Anchor, Polyvinylchloride, SIKA SARNAFIL Membrane, 11 3/4"

CATALOG NUMBER

CRAU24PW8SR2



nVent CADDY Pyramid Rooftop Anchors provide an ideal method of installing rooftop anchor points for bracing applications. The installation provides a watertight membrane seal to the roof deck. Superior membrane protection compared to other evasive anchoring and ballasting techniques that can void warranties. The anchors come in TPO, PVC and EPDM single ply materials, along with modified asphalt surface.

FEATURES

Anchors require minimal roof membrane penetration

System preserves membrane manufacturers' warranty

Matching membrane material allows for consistent performance and aesthetic

Installation creates a watertight seal, eliminating water intrusion and damage to the structure

PRODUCT ATTRIBUTES

Material: Polyvinylchloride

Membrane Manufacturer: SIKA SARNAFIL®

Color: White

Rod Size (RS): 3/8"

Diameter (Ø): 5 1/2"


Hole Size (HS): 0.28"

Width (W): 11 3/4"

ADDITIONAL PRODUCT DETAILS

Anchor system must be installed by a certified roofing contractor according to membrane manufacturer’s guidelines to preserve membrane warranty.

DIAGRAMS

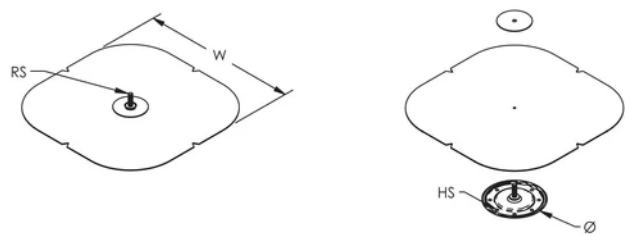

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

