

EM-P Conduit to Flange Clip



CERTIFICATIONS



FEATURES

Requires only a hammer to install

Available for EMT, rigid, IMT and aluminum conduit

Will pivot thru 360°

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	EMT Conduit Size	Rigid Conduit Size	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
12P24	3/4"	1/2"	0.870" - 1.18"	1/8"	25lb	
16P24	1"	3/4"	1.180" - 1.38"	1/8"	25lb	

CatalogNumber	EMT Conduit Size	Rigid Conduit Size	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
8P24	1/2"		0.710" - 0.87"	1/8"	25lb	ITB
12P58	3/4"	1/2"	0.870" - 1.18"	5/16" - 1/2"	25lb	
16P58	1"	3/4"	1.180" - 1.38"	5/16" - 1/2"	25lb	
8P58	1/2"		0.710" - 0.87"	5/16" - 1/2"	25lb	ITB
8P912	1/2"		0.710" - 0.87"	9/16" - 3/4"	25lb	ITB
12P912	3/4"	1/2"	0.870" - 1.18"	9/16" - 3/4"	25lb	
16P912	1"	3/4"	1.180" - 1.38"	9/16" - 3/4"	25lb	

DIAGRAMS

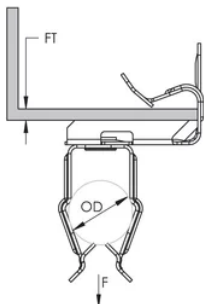

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

