

# Hammer-On Flange Clip, Bottom Mount



## CERTIFICATIONS



**BABA**



## FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

## SPECIFICATIONS

**Finish:** nVent CADDY Armour


**Material:** Spring Steel

Table 1/1

Catalog Number	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
M24	1/8" - 1/4"	1/4"	100lb	25lb	75lb
M1318	13/16" - 1 1/8"	1/4"	100lb	25lb	75lb

Catalog Number	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
M58	5/16" - 1/2"	1/4"	100lb	25lb	75lb
M912	9/16" - 3/4"	1/4"	100lb	25lb	75lb

### DIAGRAMS

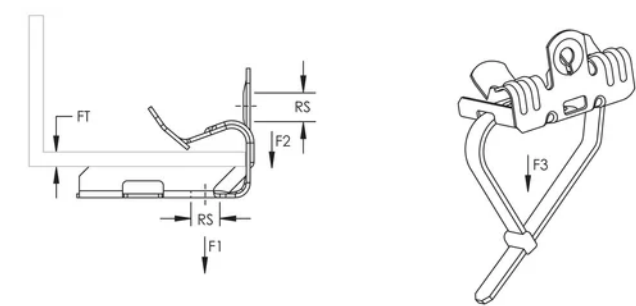

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

