

Hammer-On Flange Clip, Side Mount



CERTIFICATIONS



FEATURES

Provides an attachment for wire, S-hooks, chain, nVent CADDY Speed Link or other assemblies to flanges and profiles

Fits most beams

Installs with just a hammer


SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Static Load (F)	Certifications
2H4	Spring Steel	nVent CADDY Armour	3/32" - 9/64"	1/4"	160lb	UL, cUL, ITB
4H24SS	Stainless Steel 301 (EN 1.4310)		1/8"	1/4"	140lb	
4H24	Spring Steel	nVent CADDY Armour	1/8" - 1/4"	1/4"	200lb	UL, cUL, CE, 4H, EM, EBC, ITB

CatalogNumber	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Static Load (F)	Certifications
4H1318	Spring Steel	nVent CADDY Armour	13/16" - 1 1/8"	1/4"	200lb	UL, cUL
4H58	Spring Steel	nVent CADDY Armour	5/16" - 1/2"	1/4"	200lb	UL, CE, 4H, EM, EBC, cUL, ITB
4H58SS	Stainless Steel 301 (EN 1.4310)		5/16" - 1/2"	1/4"	140lb	
4H912	Spring Steel	nVent CADDY Armour	9/16" - 3/4"	1/4"	200lb	CE, 4H, EM, EBC, UL, ITB, cUL
4H912SS	Stainless Steel 301 (EN 1.4310)		9/16" - 3/4"	1/4"	140lb	

DIAGRAMS

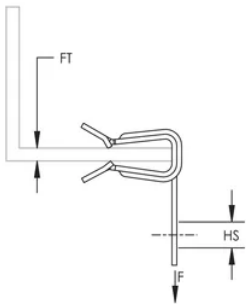

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

