


# Heavy Duty Telescoping Bracket

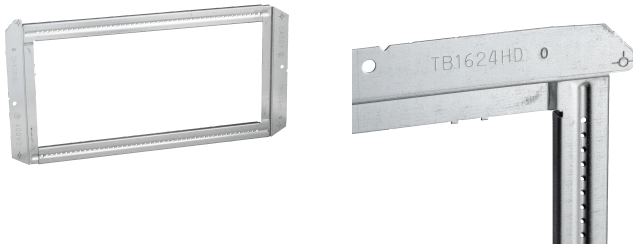

The nVent CADDY Heavy Duty Telescoping Bracket provides ultimate stud-wall flexibility, saving time on the job. This versatile box mounting system with base frame telescopes to the appropriate stud distance to allow for easy adaptation on any job site.

## CERTIFICATIONS



## FEATURES

Improved design eliminates the need to measure, allowing installation to occur 18 in from the floor to meet ADA requirements

Innovative mounting tab allows bracket to be fastened and rotated into place reducing install time

Boxes can be added or removed without detaching bracket from studs

Compatible with nVent CADDY Heavy Duty Telescoping Bracket Reinforcement Rail

Attach boxes quickly and easily with snap-on box mounting plates (sold separately)

Box mounting plates can be securely snapped in any position along fully extended bracket

Rigid design eliminates need for far-side support

Ready to use out of the box, saving installation time and labor

Works with wood or metal studs

## SPECIFICATIONS

**Finish:** Pregalvanized


Material: Steel

Table 1/1					
Catalog Number	Stud Spacing	Box Size	Length (L)	Width (W)	Height (H)
TB1624HD	14 1/2" - 25"	4", 4 11/16", 5"	14.902"	7.65"	0.45"
TB914HD	9" - 14 1/2"	4", 4 11/16", 5"	9.35"	7.296"	0.45"

ADDITIONAL PRODUCT DETAILS

For stud spacing narrower than 14.5" use the smaller TB914HD bracket.

DIAGRAMS

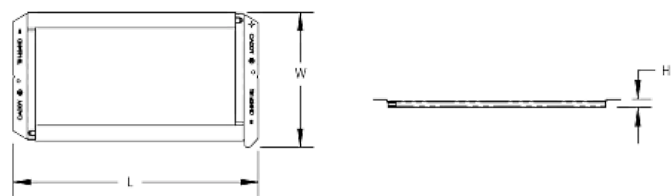

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

