


# Housed Spring Mount

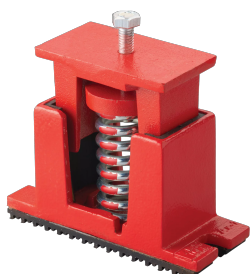

The Vibration Isolation Mount line from nVent CADDY is used to minimize vibrations produced by supported systems such as mechanical equipment, pumps, ductwork, piping, and in-line, exhaust and cabinet fans.

## FEATURES

Used to support HVAC equipment, generators, compressors, pumps, chillers and cooling towers (where lateral movement is anticipated)

Powder coated cast iron housing

Spring elements are color coded for accurate selection and easy field verification

Rubber pad provides anti-skid properties

Rubber snubber prevents metal-on-metal contact

Built-in leveling device allows for fine-tuning adjustment

## SPECIFICATIONS

Table 1/1

Catalog Number	Length	Width	Height	Ultimate Static Load	Deflection
VIBHSM1A040	2.25"	5.625"	4"	40lb	1"
VIBHSM1A065	2.25"	5.625"	4"	65lb	1"
VIBHSM1A100	2.25"	5.625"	4"	100lb	1"
VIBHSM1A200	2.25"	5.625"	4"	200lb	1"
VIBHSM1A300	2.25"	5.625"	4"	300lb	1"

Catalog Number	Length	Width	Height	Ultimate Static Load	Deflection
VIBHSM1A400	2.25"	5.625"	4"	400lb	1"
VIBHSM1A500	2.25"	5.625"	4"	500lb	1"
VIBHSM1B050	2.875"	7.5"	5.5"	50lb	1"
VIBHSM1B100	2.875"	7.5"	5.5"	100lb	1"
VIBHSM1B1000	2.875"	7.5"	5.5"	1000lb	1"
VIBHSM1B1100	2.875"	7.5"	5.5"	1100lb	1"
VIBHSM1B1200	2.875"	7.5"	5.5"	1200lb	1"
VIBHSM1B200	2.875"	7.5"	5.5"	200lb	1"
VIBHSM1B300	2.875"	7.5"	5.5"	300lb	1"
VIBHSM1B400	2.875"	7.5"	5.5"	400lb	1"
VIBHSM1B500	2.875"	7.5"	5.5"	500lb	1"
VIBHSM1B600	2.875"	7.5"	5.5"	600lb	1"
VIBHSM1B700	2.875"	7.5"	5.5"	700lb	1"
VIBHSM1B800	2.875"	7.5"	5.5"	800lb	1"
VIBHSM1B900	2.875"	7.5"	5.5"	900lb	1"
VIBHSM1C1000	2.875"	10.25"	5.75"	1000lb	1"
VIBHSM1C1200	2.875"	10.25"	5.75"	1200lb	1"
VIBHSM1C1400	2.875"	10.25"	5.75"	1400lb	1"

Catalog Number	Length	Width	Height	Ultimate Static Load	Deflection
VIBHSM1C150	2.875"	10.25"	5.75"	150lb	1"
VIBHSM1C1600	2.875"	10.25"	5.75"	1600lb	1"
VIBHSM1C1800	2.875"	10.25"	5.75"	1800lb	1"
VIBHSM1C2000	2.875"	10.25"	5.75"	2000lb	1"
VIBHSM1C2200	2.875"	10.25"	5.75"	2200lb	1"
VIBHSM1C2400	2.875"	10.25"	5.75"	2400lb	1"
VIBHSM1C300	2.875"	10.25"	5.75"	300lb	1"
VIBHSM1C400	2.875"	10.25"	5.75"	400lb	1"
VIBHSM1C600	2.875"	10.25"	5.75"	600lb	1"
VIBHSM1C800	2.875"	10.25"	5.75"	800lb	1"
VIBHSM2A040	2.875"	7.5"	5.5"	40lb	2"
VIBHSM2A065	2.875"	7.5"	5.5"	65lb	2"
VIBHSM2A100	2.875"	7.5"	5.5"	100lb	2"
VIBHSM2A200	2.875"	7.5"	5.5"	200lb	2"
VIBHSM2A300	2.875"	7.5"	5.5"	300lb	2"
VIBHSM2A400	2.875"	7.5"	5.5"	400lb	2"
VIBHSM2A500	2.875"	7.5"	5.5"	500lb	2"
VIBHSM2B050	2.875"	7.5"	6.5"	50lb	2"

Catalog Number	Length	Width	Height	Ultimate Static Load	Deflection
VIBHSM2B100	2.875"	7.5"	6.5"	100lb	2"
VIBHSM2B1000	2.875"	7.5"	6.5"	1000lb	2"
VIBHSM2B1100	2.875"	7.5"	6.5"	1100lb	2"
VIBHSM2B1200	2.875"	7.5"	6.5"	1200lb	2"
VIBHSM2B200	2.875"	7.5"	6.5"	200lb	2"
VIBHSM2B300	2.875"	7.5"	6.5"	300lb	2"
VIBHSM2B400	2.875"	7.5"	6.5"	400lb	2"
VIBHSM2B500	2.875"	7.5"	6.5"	500lb	2"
VIBHSM2B600	2.875"	7.5"	6.5"	600lb	2"
VIBHSM2B700	2.875"	7.5"	6.5"	700lb	2"
VIBHSM2B800	2.875"	7.5"	6.5"	800lb	2"
VIBHSM2B900	2.875"	7.5"	6.5"	900lb	2"
VIBHSM2C1000	2.875"	10.5"	6.75"	1000lb	2"
VIBHSM2C1200	2.875"	10.5"	6.75"	1200lb	2"
VIBHSM2C1400	2.875"	10.5"	6.75"	1400lb	2"
VIBHSM2C150	2.875"	10.5"	6.75"	150lb	2"
VIBHSM2C1600	2.875"	10.5"	6.75"	1600lb	2"
VIBHSM2C1800	2.875"	10.5"	6.75"	1800lb	2"

Catalog Number	Length	Width	Height	Ultimate Static Load	Deflection
VIBHSM2C2000	2.875"	10.5"	6.75"	2000lb	2"
VIBHSM2C2200	2.875"	10.5"	6.75"	2200lb	2"
VIBHSM2C2400	2.875"	10.5"	6.75"	2400lb	2"
VIBHSM2C300	2.875"	10.5"	6.75"	300lb	2"
VIBHSM2C400	2.875"	10.5"	6.75"	400lb	2"
VIBHSM2C600	2.875"	10.5"	6.75"	600lb	2"
VIBHSM2C800	2.875"	10.5"	6.75"	800lb	2"

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

