


# Improved nVent CADDY Cat HP J-Hook Mod Clip with BC Beam Clamp

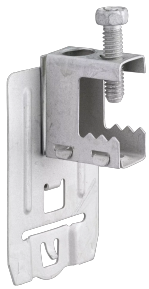

The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC Beam Clamp simplifies beam flange installation with an easy-to-use design. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

## CERTIFICATIONS



## FEATURES

Easy beam flange installation

Works with nVent J-Hook Versa-Mount technology from nVent CADDY


## SPECIFICATIONS

Table 1/1

Catalog Number	Finish	Material	Flange Thickness (FT)	Static Load (F)
CATHPMBC	Electrogalvanized, nVent CADDY Armour	Steel, Spring Steel	0.63" Max	100lb

## DIAGRAMS

---

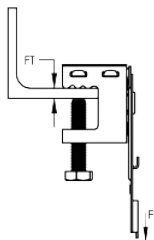

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

