


Improved nVent CADDY Cat HP J-Hook Mod Clip with Hammer-On Flange Clip



The Improved nVent CADDY Cat HP Mod Clip J-Hook Clip with Hammer-On Flange Clip simplifies beam flange installation with an easy-to-use design. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

CERTIFICATIONS

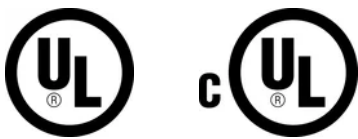

FEATURES

Requires only a hammer to install

Works with nVent J-Hook Versa-Mount technology from nVent CADDY

SPECIFICATIONS


Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/1

Catalog Number	Flange Thickness (FT)	Static Load (F)
CATHPM58SM	0.3" - 0.5"	200lb
CATHPM912SM	0.56" - 0.75"	200lb

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

