


MC/AC Trapeze Support

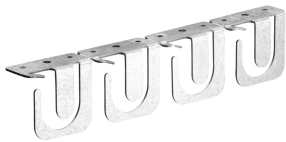

The nVent CADDY MCS Trapeze (MCST) is a fast and cost-effective method for installing a wide range of MC/AC cable in overhead and trapeze installations. The MCST series eliminates the need for traditional fasteners, reducing installation time and material cost. The break-apart design feature makes it simple to field modify, providing an ideal solution for contractors looking to maximize installation efficiency.

CERTIFICATIONS



FEATURES

Shot fire flange for direct attachment to ceiling/deck

Easy to use break-apart feature for easy field modification

Properly spaces MC/AC cable to help eliminate bundling and NEC® and CEC derating issues

Up to 50% installation time savings over traditional methods

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	MC/AC Cable Size	Super Neutral Cable Size	Outer Diameter (OD)	Cable Capacity	Length 1 (L1)	Length 2 (L2)
MCS100TX4	14-3 to 10-2	10-2	0.43" - 0.56"	32	3"	12"
MCS100TX8	14-3 to 10-2	10-2	0.43" - 0.56"	64	3"	24"


CatalogNumber	MC/AC Cable Size	Super Neutral Cable Size	Outer Diameter (OD)	Cable Capacity	Length 1 (L1)	Length 2 (L2)
MCS101TX4	10-3 to 8-3	12-3 to 10-2	0.56" - 0.69"	28	3"	12"
MCS101TX8	10-3 to 8-3	12-3 to 10-2	0.56" - 0.69"	56	3"	24"

Table 2/2			
Catalog Number	Height (H)	Hole Size 1 (HS1)	Hole Size 2 (HS2)
MCS100TX4	2.5"	0.2"	0.25"
MCS100TX8	2.5"	0.2"	0.25"
MCS101TX4	2.5"	0.2"	0.25"
MCS101TX8	2.5"	0.2"	0.25"

ADDITIONAL PRODUCT DETAILS

Accommodates 1/4" threaded rod trapeze drops.

DIAGRAMS

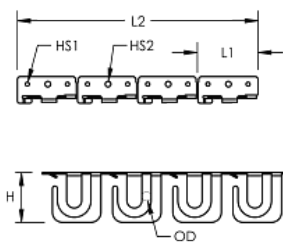

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

