


nVent CADDY Box Mounting Plate with Far Side Support on Stud Assembly

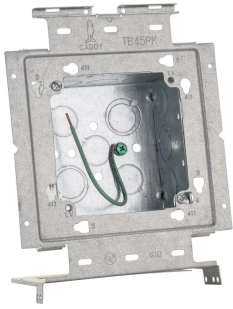

The nVent CADDY Box Mounting Plate with Far Side Support on Stud Assembly line increases overall productivity, savings, and job site safety. For ultimate flexibility, the assemblies are configured with the most common box and mud ring combinations. The line is also offered in both standard and open back boxes as well as in single and double gang fixed or adjustable depth mud rings. When paired with the nVent CADDY Open Back Box, the assembly is ideal for prefab installations where devices, fittings, and cables are installed to quickly and easily complete make-up wiring connections, without the need to drop or work through the mud ring.

CERTIFICATIONS



FEATURES

Snap-on installation to Heavy Duty Telescoping Bracket allows for easy positioning along bracket

Can also be mounted directly to metal or wood studs

Innovative far side support allows bracket to be installed on virtually any stud depth and up to 3" wide studs

Extruded holes allow mounting of mud rings for both power and data applications

Key holes provide ease of installation and positive location when mounting boxes

Accepts vertically or horizontally mounted single and double gang adjustable mud rings

Box Lock tab secures box to bracket during assembly and allows mud ring to be removed following installation on the stud, providing easy frontal access to the inside of the box

Box Lock feature is ideal for prefab assemblies

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Knockout Sizes	Box Depth	Box Size	Box Type	Box Volume	Drywall Thickness
PKX4V2	(4) 1/2", 3/4", (7) 1/2"	2.12"	4"	Open	32.8in ³	1" - 1 1/2"
PKX4M1	(4) 1/2", 3/4", (7) 1/2"	2.12"	4"	Open	32.8in ³	5/8"
PKX4M2	(4) 1/2", 3/4", (7) 1/2"	2.12"	4"	Open	32.8in ³	5/8"
PK4DV2	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	Closed	30.3in ³	5/8" - 1 1/2"
PK4DM1	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	Closed	30.3in ³	3/4"
PK4DM2	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	Closed	30.3in ³	3/4"
PKD1M5	(4) 1", (4) 1-1/4"	2.12"	4 11/16"	Closed	42in ³	3/4"
PKP1M5	(12) 1/2", 3/4"	2.12"	4 11/16"	Closed	42in ³	3/4"
PKP1M6	(12) 1/2", 3/4"	2.12"	4 11/16"	Closed	42in ³	3/4"
PK4DV1	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	Closed	30.3in ³	3/4" - 1 1/2"
PKX4V1	(4) 1/2", 3/4", (7) 1/2"	2.12"	4"	Open	32.8in ³	5/8" Min
PK4D	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	Closed	30.3in ³	
PKD1	(4) 1", (4) 1-1/4"	2.12"	4 11/16"	Closed	42in ³	
PKP1	(12) 1/2", 3/4"	2.12"	4 11/16"	Closed	42in ³	
PKX4	(4) 1/2", 3/4", (7) 1/2"	2.12"	4"	Open	32.8in ³	

Table 2/2

Catalog Number	Gang	Ground Wire Included	Mud Ring Type	Certifications
PKX4V2	2	Yes	Adjustable	UL

Catalog Number	Gang	Ground Wire Included	Mud Ring Type	Certifications
PKX4M1	1	Yes	Raised	
PKX4M2	2	Yes	Raised	UL
PK4DV2	2	Yes	Adjustable	
PK4DM1	1	Yes	Raised	
PK4DM2	2	Yes	Raised	
PKD1M5	1	Yes	Raised	
PKP1M5	1	Yes	Raised	
PKP1M6	2	Yes	Raised	
PK4DV1	1	Yes	Adjustable	
PKX4V1	1	Yes	Adjustable	UL
PK4D		Yes		
PKD1		Yes		
PKP1		Yes		
PKX4		Yes		

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

