


nVent CADDY Cable/Conduit Stud Attachment, Multifunction



The nVent CADDY Cable/Conduit Stud Attachment, Multifunction is a simplified, easy-to-use solution for mounting both EMT and flexible conduit above electrical boxes. Its universal design eliminates the need to carry multiple parts on the job and allows contractors to utilize just one fastener. Additionally, the Cable/Conduit Stud Attachment, Multifunction increases functionality by featuring a wider bracket to span across the entirety of the electrical box and reach all three knockouts. Whether you're securing EMT, flexible conduit or both, rest assured, this simple solution improves productivity while keeping your job site safe.

CERTIFICATIONS

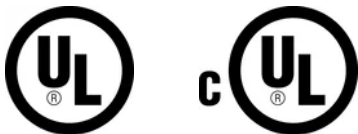

FEATURES

Multifunction design allows for different securement combinations such as one EMT and up to two flexible conduit cables or three conduit cables

Capable of securing EMT sizes spanning from ½ to 1 in

Score marks to break off excess bracket

Compliant with NEC® Article 358.30(A), which requires conduit support within 36 in of an electrical box

Compliant with CEC Rule 12-1404, which requires conduit support within 1 m of an electrical box


Compliant with CEC Rule 12-618, which requires support of armored cable within 300 mm (12 in) of an electrical box

SPECIFICATIONS

Table 1/2						
Catalog Number	Material	Finish	EMT Conduit Size	MC/AC Cable Size	Outer Diameter 1 (OD1)	Outer Diameter 2 (OD2)
CS816M	Steel	nVent CADDY Armour	0.5" - 1"	14-2 to 2-3	0.5" Max	0.5" Max

Table 2/2		
Catalog Number	Outer Diameter (OD)	Box Depth
CS816M	0.500" - 1.163"	2.125"

DIAGRAMS

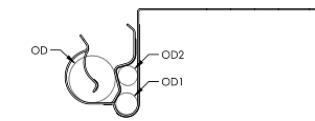

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

