


nVent CADDY Heavy Duty Telescoping Bracket Assembly with Fire Alarm Box

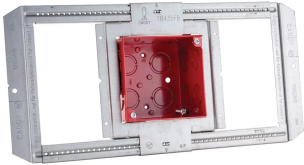

The nVent CADDY Heavy Duty Telescoping Bracket Assembly with Fire Alarm Box increases overall productivity, savings, and job site safety. For ultimate flexibility, the assembly is configured with the most common box and mud ring combination. The box is powder-coated and adjustable for mounting fire alarm devices and strobes, designed for on-stud and between-stud applications. With two screws inside the box, installers can easily adjust to different depths after installation of drywall or ceiling tiles.

FEATURES

Rigid and versatile - add/remove boxes quickly and easily

Prefab tab to prevent disassembly during transport, but allows for sliding on main bracket prior to final securement

Bracket will telescope and allow for easy positioning within wall stud

Box center plates slide to desired position prior to final securement

Used for mounting fire alarm devices and strobes

Screws inside fire alarm box allow for adjustment after drywall or ceiling tile installation, providing confidence to adapt to any situation

Easily adjusts from 1/2" to 1-1/2" for different depth wall and ceiling applications

Design provides built in far side support for 3-5/8" stud depths

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Color	Knockout Sizes	Box Depth	Box Size
TBFB	Steel	Pregalvanized, Powder Coated	Red	1/2", 3/4"	3 1/2"	4"

Table 2/2

Catalog Number	Drywall Thickness	Ground Wire Included	Stud Spacing
TBFB	5/8" - 1 1/2"	No	14 1/2" - 25"

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

