


nVent CADDY Heavy Duty Telescoping Bracket T-Grid Assembly, Fire Alarm Box

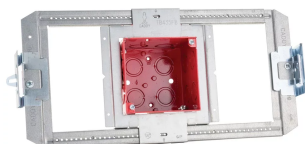

The nVent CADDY Heavy Duty Telescoping Bracket T-Grid Assembly with Fire Alarm Box increases overall productivity, savings, and job site safety. For ultimate flexibility, the assembly is configured with the most common box and mud ring combination. The box is powder-coated and adjustable for mounting fire alarm devices and strobes between T-grid using box mounting plates. With simple clips, installers can easily fasten to the Heavy Duty Telescoping Bracket with just one screw.

CERTIFICATIONS



FEATURES

Prefab tab to prevent disassembly during transport, but allows for sliding on main bracket prior to final securement

For use with Heavy Duty Telescoping Box Bracket Assembly to install junction boxes, fire alarm devices and strobes between T-grid using box mounting plates

Snap-on design eliminates the need for attachment screw to T-grid

Boxes can be easily positioned between the T-grid by sliding across the nVent CADDY Heavy Duty Telescoping Bracket

Accommodates ceiling tile up to 1-1/4" thick

Clip snaps onto nVent CADDY Heavy Duty Telescoping Bracket and fastens with one screw

SPECIFICATIONS

Material: Steel

Table 1/2

Catalog Number	Finish	Color	Knockout Sizes	Box Depth	Box Size	Drywall Thickness
----------------	--------	-------	----------------	-----------	----------	-------------------

TBTFB	Pregalvanized, Powder Coated	Red	1/2", 3/4"	3 1/2"	4"	5/8" - 1 1/2"
TBT	Pregalvanized					

Table 2/2		
Catalog Number	Ground Wire Included	Certifications
TBTFB	No	
TBT		UL

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

