


# nVent CADDY Pyramid Crossover Platform

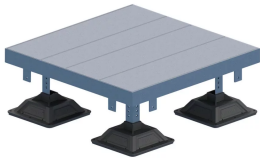

## FEATURES

Height adjustable interlocking platforms allow for quick and easy installation of a custom pathway across rooftop surfaces

Protect roof surfaces by providing a clearly defined pathway

Modular design allows for easily configurable heights and lengths to address varying applications

nVent CADDY Pyramid bases provide superior load distribution and roof membrane compatibility

Foam bottom offers low abrasion interface for better roof membrane protection

Aluminum construction designed to withstand harsh environments


Walking surfaces with serrated tread provides maximum slip resistance and drainage

## SPECIFICATIONS

Table 1/1

Catalog Number	Material	Depth (D)	Height (H)	Width (W)	Static Load (F)
PCP36	Aluminum, Polypropylene, Polyethylene	36"	11" - 14"	36"	500lb

DIAGRAMS

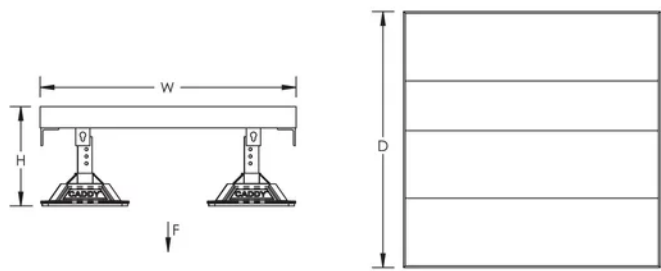

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

