

# nVent CADDY Pyramid RL Adjustable Roller Support



## FEATURES

Height-adjustable roller-based support designed specifically for rooftop applications

Height adjustability allows for effective navigation of pipe around obstructions

Polymeric rollers ensure corrosion free rotation

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Ready to use out of the box, saving installation time and labor

Hot-dip galvanized and UV stabilized for long lasting performance

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	3:1
<b>Finish:</b>	Hot-Dip Galvanized
<b>Material:</b>	Polyethylene;Polypropylene;Steel
<b>Temperature:</b>	-50 to 150 °F


Table 1/2

Catalog Number	Pipe Size	Height (H)	Length (L)	Width (W)	A	Surface Area
PRA3H12	3" Max	6" - 12"	12 1/2"	8"	6 1/4"	92in <sup>2</sup>
PRA6H16	6" Max	6 1/2" - 16"	19"	8"	10 1/4"	142in <sup>2</sup>

Table 2/2

Catalog Number	Unit Weight	Static Load (F)
PRA3H12	4 lb	250lbf
PRA6H16	5 lb	600lbf

## DIAGRAMS

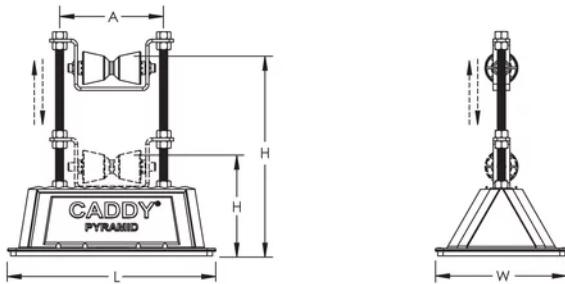

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

