

# nVent CADDY Pyramid Rooftop Anchor



nVent CADDY Pyramid Rooftop Anchors provide an ideal method of installing rooftop anchor points for bracing applications. The installation provides a watertight membrane seal to the roof deck. Superior membrane protection compared to other evasive anchoring and ballasting techniques that can void warranties. The anchors come in TPO, PVC and EPDM single ply materials, along with modified asphalt surface.

## FEATURES

Anchors require minimal roof membrane penetration

System preserves membrane manufacturers' warranty

Matching membrane material allows for consistent performance and aesthetic

Installation creates a watertight seal, eliminating water intrusion and damage to the structure

## SPECIFICATIONS

Table 1/2

Catalog Number	Material	Membrane Manufacturer	Color	Rod Size (RS)	Diameter (Ø)
CRAU24EB1C	EPDM-SBR Rubber	CARLISLE®	Black	3/8"	5 1/2"
CRAU24EB1CR2	EPDM-SBR Rubber	CARLISLE®	Black	3/8"	5 1/2"
CRAU24PW3J	Polyvinylchloride	JOHNS MANVILLE®	White	3/8"	5 1/2"
CRAU24PW3JR2	Polyvinylchloride	JOHNS MANVILLE®	White	3/8"	5 1/2"
CRAU24PW8S	Polyvinylchloride	SIKA SARNAFIL®	White	3/8"	5 1/2"
CRAU24PW8SR2	Polyvinylchloride	SIKA SARNAFIL®	White	3/8"	5 1/2"

Catalog Number	Material	Membrane Manufacturer	Color	Rod Size (RS)	Diameter (Ø)
CRAU24TW1C	Thermoplastic Polyolefin (TPO)	CARLISLE®	White	3/8"	5 1/2"
CRAU24TW1CR2	Thermoplastic Polyolefin (TPO)	CARLISLE®	White	3/8"	5 1/2"
CRAU24TW2F	Thermoplastic Polyolefin (TPO)	FIRESTONE®	White	3/8"	5 1/2"
CRAU24TW2FR2	Thermoplastic Polyolefin (TPO)	FIRESTONE®	White	3/8"	5 1/2"
CRAU24TW3J	Thermoplastic Polyolefin (TPO)	JOHNS MANVILLE®	White	3/8"	5 1/2"
CRAU24TW3JR2	Thermoplastic Polyolefin (TPO)	JOHNS MANVILLE®	White	3/8"	5 1/2"
CRAU24TW4G	Thermoplastic Polyolefin (TPO)	GAF®	White	3/8"	5 1/2"
CRAU24TW4GR2	Thermoplastic Polyolefin (TPO)	GAF®	White	3/8"	5 1/2"
CRAU26ST2F	Modified Asphalt	FIRESTONE®	Black	3/8"	5 1/2"
CRAU26ST2FR2	Modified Asphalt	FIRESTONE®	Black	3/8"	5 1/2"
CRAU26STCR2F	Modified Asphalt	FIRESTONE®	Black	3/8"	5 1/2"
CRAU26STCR2FR2	Modified Asphalt	FIRESTONE®	Black	3/8"	5 1/2"
CRAU26SW12C	Modified Asphalt	CERTAINTEED®		3/8"	5 1/2"
CRAU26SW12CR2	Modified Asphalt	CERTAINTEED®	Black	3/8"	5 1/2"

Table 2/2


Catalog Number	Hole Size (HS)	Width (W)
CRAU24EB1C	0.28"	11 3/4"
CRAU24EB1CR2	0.28"	11 3/4"
CRAU24PW3J	0.28"	11 3/4"

Catalog Number	Hole Size (HS)	Width (W)
CRAU24PW3JR2	0.28"	11 3/4"
CRAU24PW8S	0.28"	11 3/4"
CRAU24PW8SR2	0.28"	11 3/4"
CRAU24TW1C	0.28"	11 3/4"
CRAU24TW1CR2	0.28"	11 3/4"
CRAU24TW2F	0.28"	11 3/4"
CRAU24TW2FR2	0.28"	11 3/4"
CRAU24TW3J	0.28"	11 3/4"
CRAU24TW3JR2	0.28"	11 3/4"
CRAU24TW4G	0.28"	11 3/4"
CRAU24TW4GR2	0.28"	11 3/4"
CRAU26ST2F	0.28"	18"
CRAU26ST2FR2	0.28"	18"
CRAU26STCR2F	0.28"	18"
CRAU26STCR2FR2	0.28"	18"
CRAU26SW12C	0.28"	18"
CRAU26SW12CR2	0.28"	18"

ADDITIONAL PRODUCT DETAILS

Anchor system must be installed by a certified roofing contractor according to membrane manufacturer’s guidelines to preserve membrane warranty.

DIAGRAMS

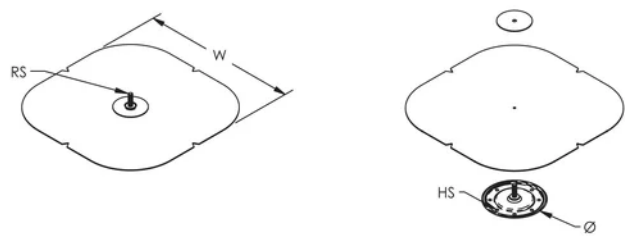

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

