

nVent CADDY Pyramid Tool-Free Pipe Support Kit



FEATURES

Push-in clamps install without the need for additional tools or strut clamps

Ready to use out of the box, saving installation time and labor

Plastic clamps and base will not corrode pipe

Clamps come in two different sizes to fit project needs

Base includes multiple holes to accommodate a variety of clamp sizes and configurations

Additional clamps can be purchased separately for additional pipe runs

Foam bottom offers low abrasion interface for better roof membrane protection

Provides superior load distribution, even with varying rooftop surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Easy to transport to the roof

SPECIFICATIONS

Static Load Safety Factor:	3:1
Material:	Polyethylene;Polypropylene;Nylon
Temperature:	-50 to 150 °F

Table 1/2

Catalog Number	Length 1 (L1)	Length 2 (L2)	Length 3 (L3)	Width (W)	Height (H)	A
----------------	---------------	---------------	---------------	-----------	------------	---

PTF6	7.72"		3.19"	5.91"	4.02"	4.8"
PTF10	12.52"	4.8"	6.42"	7.91"	4.02"	8"
PTF16	18.9"	7.99"	9.61"	7.91"	4.02"	11.22"

Table 2/2				
Catalog Number	B	Surface Area	Unit Weight	Static Load (F)
PTF6	1.61"	41in ²	0.6 lb	300lb
PTF10	1.61"	92in ²	1 lb	1000lb
PTF16	1.61"	142in ²	2 lb	1500lb


ADDITIONAL PRODUCT DETAILS

Length 2 represents maximum pipe center to pipe center using PTF2C clamps. Length 3 represents maximum pipe center to pipe center using PTF1C clamps.

Tool-Free Pipe Clamp				
Part Number	Outer Diameter OD	A	B	C
PTF1C	0.50" – 1.32"	3/8"	1.6"	3/4"
PTF2C	0.84" – 2.38"	3/8"	3.2"	3/4"

Part Number	Number of Clamps Included		Maximum Clamp Capacity	
	PTF1C	PTF2C	PTF1C	PTF2C
PTF6	1	1	3	1
PTF10	-	2	5	2
PTF16	-	2	7	3

DIAGRAMS

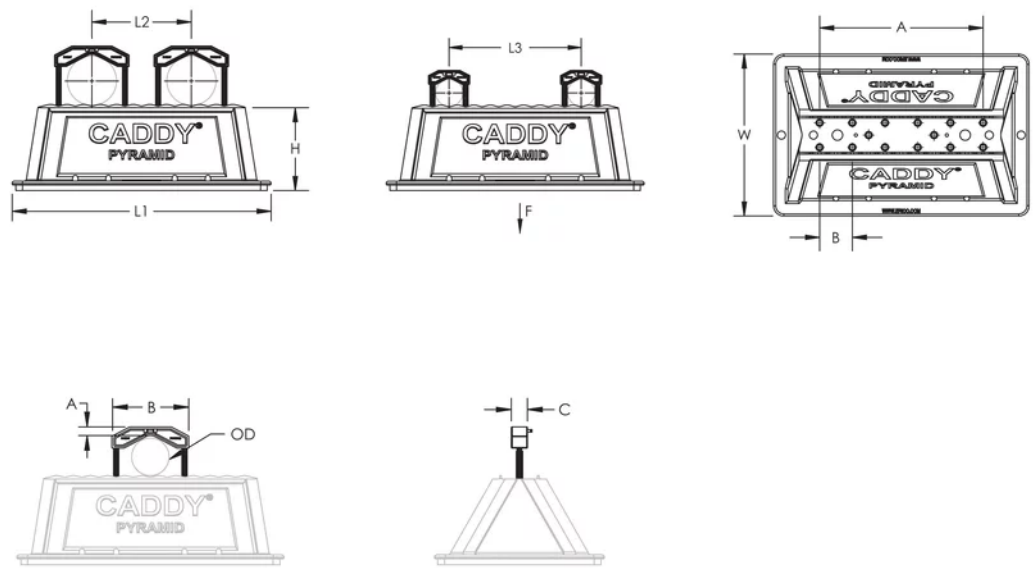

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

