

# nVent CADDY Rod Lock Metal Decking Preset Anchor Insert



## FEATURES

Allows for the installation of leveled nVent CADDY Rod Lock Metal Decking Preset Anchors anywhere between the metal decking ribs

Symmetrical design with two insert holes for each size of Rod Lock Metal Decking Preset Anchors

Compatible with a very wide range of metal decking

Rod Lock Metal Decking Preset Anchors can be easily inserted through the insert plate while maintaining a tight positioning of the anchor

Holes on each end of the insert for fixing to metal deck with self-tapping screws or nail gun

Quick and easy installation

## SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)	Length (L)
CRLMIP	Steel	Pregalvanized	3/4"	7/8"	0.26"	12"

Table 2/2

Catalog Number	Width (W)	Thickness (T)	A	B
CRLMIP	1 1/2"	0.14"	3" Max	10" Max

DIAGRAMS

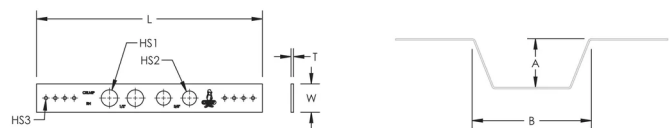

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

