


nVent CADDY Rod Lock Spring Steel Rod Hanger to Beam Clamp



CERTIFICATIONS

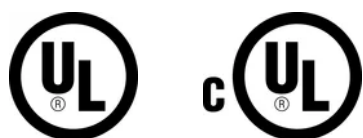

FEATURES

Suspends threaded rod from beam flanges

Threaded rod hanger can swivel to provide a vertical dropdown

Easy "push-to-install" design allows installers to simply push the threaded rod through the mounting hole, instantly holding it in position

Prefabricated assemblies easily lift and lock into place, helping to save time and money

Works with slightly damaged threads and minor burrs on threaded rod ends

Design includes a release mechanism that works with pliers


SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Rod Size (RS)	Flange Thickness (FT)	Hole Size (HS)	Torque (TQ)
4QTIBC	Spring Steel	nVent CADDY Armour	1/4"	1/2" Max	7/16"	20 ft·lbf

Table 2/2	
Catalog Number	Static Load (F)
4QTIBC	75lbf

DIAGRAMS

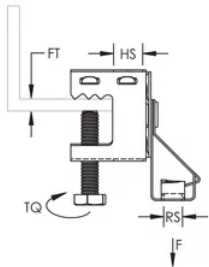

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

