

# nVent CADDY Speed Link LD with Hook



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

## SPECIFICATIONS

<b>Wire Rope Diameter:</b>	1.5 mm
<b>Static Load Safety Factor:</b>	5:1
<b>Material:</b>	Stainless Steel 304 (EN 1.4301)

Table 1/1

Catalog Number	Wire Rope Length	A	B	C	Static Load (F)
SLD15L10S	32.8'	2.3"	0.9"	1/4"	44lbf


Catalog Number	Wire Rope Length	A	B	C	Static Load (F)
SLD15L2S	6.6'	2.3"	0.9"	1/4"	44lbf
SLD15L5S	16.4'	2.3"	0.9"	1/4"	44lbf

**Width (W):** 1/2"  
**Height (H):** 3/4"

### ADDITIONAL PRODUCT DETAILS

Wire and pre-assembled hook end fitting made of Stainless Steel 316 (1.4401).

### DIAGRAMS

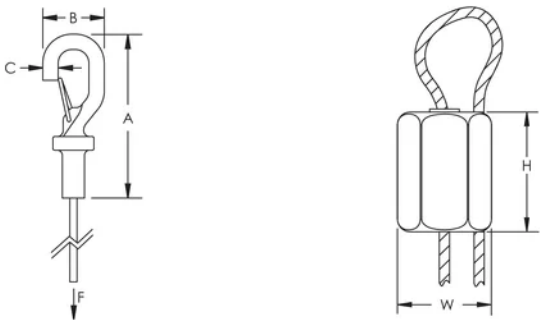

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

