

# nVent CADDY Speed Link SLK with Angle Bracket



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Zinc Alloy;Polypropylene
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)	Width (W)
SLK15L1AB	1.5 mm	3.3'	0.89"	0.28"	2.15"	3/4"


CatalogNumber	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)	Width (W)
SLK15L2AB	1.5 mm	6.6'	0.89"	0.28"	2.15"	3/4"
SLK15L3AB	1.5 mm	9.9'	0.89"	0.28"	2.15"	3/4"
SLK15L5AB	1.5 mm	16.4'	0.89"	0.28"	2.15"	3/4"
SLK2L2AB	2 mm	6.6'	0.89"	0.28"	2.15"	3/4"
SLK2L3AB	2 mm	9.9'	0.89"	0.28"	2.15"	3/4"
SLK2L5AB	2 mm	16.4'	0.89"	0.28"	2.15"	3/4"
SLK3L10AB	3 mm	32.8'	0.89"	0.28"	2 1/2"	0.9"
SLK3L5AB	3 mm	16.4'	0.89"	0.28"	2 1/2"	0.9"
SLK3L7AB	3 mm	22.9'	0.89"	0.28"	2 1/2"	0.9"

Table 2/2

Catalog Number	Thickness (T)	Angle (a)	Static Load (F)	Certifications
SLK15L1AB	1/2"	90 ° Max	44lbf	UL, cUL, ITB
SLK15L2AB	1/2"	90 ° Max	44lbf	ITB, UL, cUL
SLK15L3AB	1/2"	90 ° Max	44lbf	ITB, UL, cUL
SLK15L5AB	1/2"	90 ° Max	44lbf	ITB, UL, cUL
SLK2L2AB	1/2"	90 ° Max	100lbf	ITB, UL, cUL
SLK2L3AB	1/2"	90 ° Max	100lbf	ITB, UL, cUL
SLK2L5AB	1/2"	90 ° Max	100lbf	UL, cUL, ITB
SLK3L10AB	0.6"	90 ° Max	200lbf	

Catalog Number	Thickness (T)	Angle (a)	Static Load (F)	Certifications
SLK3L5AB	0.6"	90 ° Max	200lbf	
SLK3L7AB	0.6"	90 ° Max	200lbf	

### DIAGRAMS

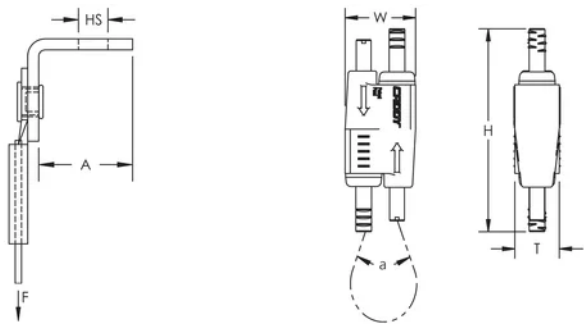

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

