

nVent CADDY Speed Link SLK with Hammer-On Flange Clip



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled nVent CADDY Hammer-On Flange Clip end fitting

Installs with just a hammer

Fits most beams

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy
Complies With:	SMACNA HVAC-DCS


Table 1/1

Catalog Number	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load (F)
SLK2L34H24	2 mm	9.9'	1/8"	100lbf

Catalog Number	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load (F)
SLK15L34H24	1.5 mm	9.9'	1/8"	44lbf
SLK15L34H58	1.5 mm	9.9'	5/16" - 1/2"	44lbf
SLK2L34H58	2 mm	9.9'	5/16" - 1/2"	100lbf

Thickness (T): 1/2"
Width (W): 3/4"
Height (H): 2.15"
Angle (a): 90 ° Max

DIAGRAMS

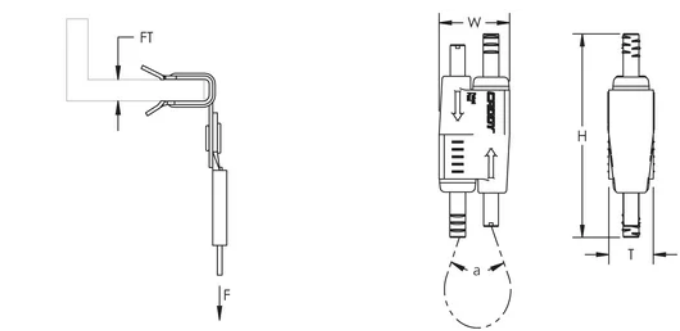

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

